

## COWO Fiber Customer Wall Outlet

COWO is a fiber optic customer outlet that allows easy and unobtrusive termination of fiber optic cables in an office, home or communications room.

### Features

- Accommodates two termination/splice connections
- 2 SC simplex or 1 LC duplex adapters
- 2 crimp, mechanical or heat shrink splices
- IP20 rated
- Very flat design, mounts on a standard flush mount electrical outlet
- Utilizes reduced bend radius fiber (G657.A and B)
- Possibility to invert the adapter in the holder to prevent disconnection when pulling the patch cords
- RoHS compliant
- Conforms to UL 94 V-0
- Lockable with screw or lead-wire seal
- Cable entrance from the bottom, left and rear
- Made of molded plastic (halogen free, LSZH-1), white (RAL 9010)

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Fiber wall outlet
<b>Product Series</b>	COWO

## General Specifications

<b>Color</b>	White
<b>Cover Type</b>	Hinged with latches
<b>Lock Type</b>	Lead-wire seal
<b>Mounting</b>	Wall mount


## Dimensions

# COWO

---

<b>Height</b>	115.062 mm   4.53 in
<b>Depth</b>	24.384 mm   0.96 in
<b>Length</b>	80.01 mm   3.15 in

## Outline Drawing

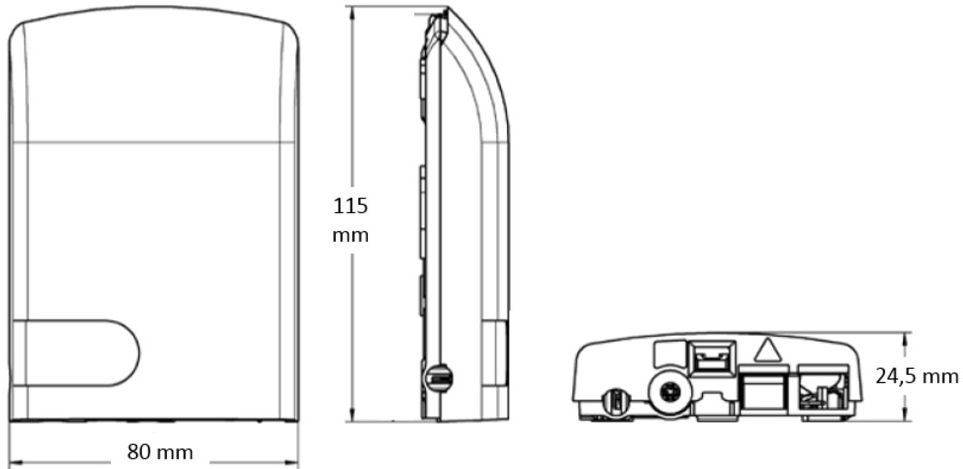

## Material Specifications

**Material Type** LSZH thermoplastic

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Environmental Space** Indoor