



Fiber Optic Drop Cable Assembly for outdoor buried applications

Product Classification

Portfolio	CommScope®
Product Type	Fiber drop cable assembly


General Specifications

Cable Type	Dielectric - Flat
Construction Type	Breakout, armored
Jacket Color	Black

Dimensions

Cable Outer Diameter	4.3 x 8.0 mm (0.17 x 0.31 in)
-----------------------------	-------------------------------

Representative Image

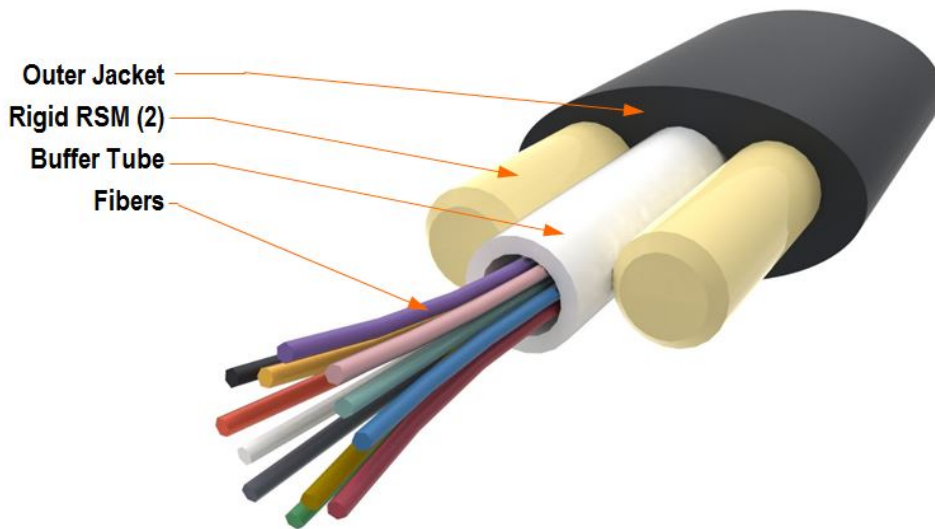

FD

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Installation temperature	-30 °C to +70 °C (-22 °F to +158 °F)
Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +75 °C (-40 °F to +167 °F)
Environmental Space	Outdoor, buried
Jacket UV Resistance	UV stabilized
Qualification Standards	IEC 60529, IP68 Telcordia GR-326

Packaging and Weights

Packaging quantity	1
---------------------------	---