

Micro Duct Cable Closure Kit for 26-way micro duct or 3+12 Ribbonet and up to 6pcs 7.2mm 1-way micro duct joint

- Waterproof closure for micro duct cable connections in outside plant networks
- Fast and easy installation and re-entry process with the gel-sealing system
- No special tools or sealing replacement material required for installation and re-entry

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Micro duct cable closure
Product Series	MDCC


General Specifications

Cable Entry Drop Port Style	Round
Cable Entry Main Port Style	Round
Cable Ports, quantity	5
Cable Sealing Type	Compressed gel
Closure Sealing Type	Hinged with wedge
Closure Style	In-line
Color	Black
Mounting	Wall
Network Area Type	Distribution

Dimensions

Height	50 mm 1.969 in
Width	135 mm 5.315 in
Length	320 mm 12.598 in
Main Cable Diameter, maximum	35 mm 1.378 in

Dimension Drawing

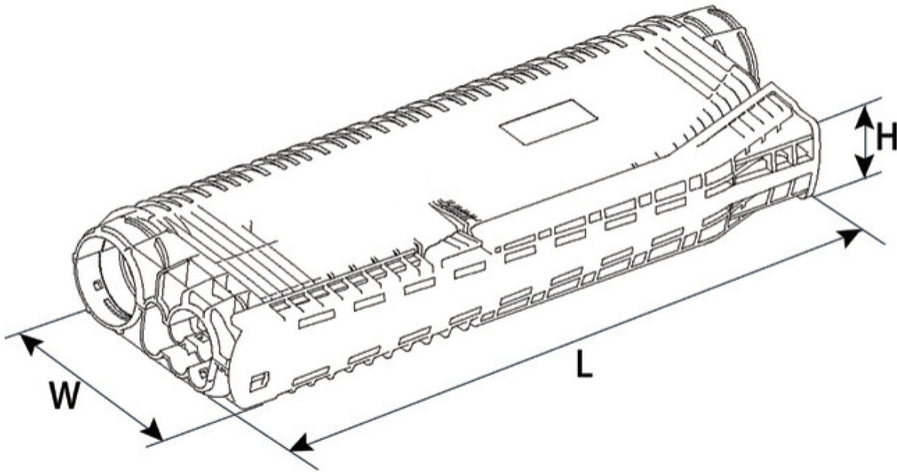

Material Specifications

Material Type Rugged polymer

Environmental Specifications

Environmental Space Below ground | Buried

Qualification Standards IEC 61300, 1 m waterhead

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Weight, net 0.8 kg | 1.764 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ROHS	Compliant
UK-ROHS	Compliant

